


Circuit scheme:

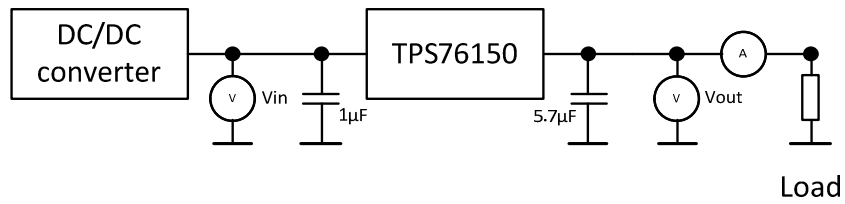

Measure results:

Load [A]	V_{in} [V]	V_{out} [V]
20.00E-3	6.46E+0	5.03E+0
30.00E-3	6.41E+0	5.02E+0
40.00E-3	6.35E+0	5.02E+0
50.00E-3	6.30E+0	5.01E+0
60.00E-3	6.26E+0	5.01E+0
70.00E-3	6.21E+0	5.00E+0
80.00E-3	6.17E+0	5.00E+0
90.00E-3	6.13E+0	5.00E+0
100.00E-3	6.09E+0	4.99E+0
110.00E-3	6.05E+0	4.99E+0
120.00E-3	6.01E+0	4.98E+0
130.00E-3	5.97E+0	4.98E+0
140.00E-3	5.93E+0	4.96E+0
150.00E-3	5.89E+0	4.86E+0
160.00E-3	5.86E+0	3.73E+0
162.00E-3	5.88E+0	3.62E+0
163.00E-3	5.93E+0	37.00E-3

