


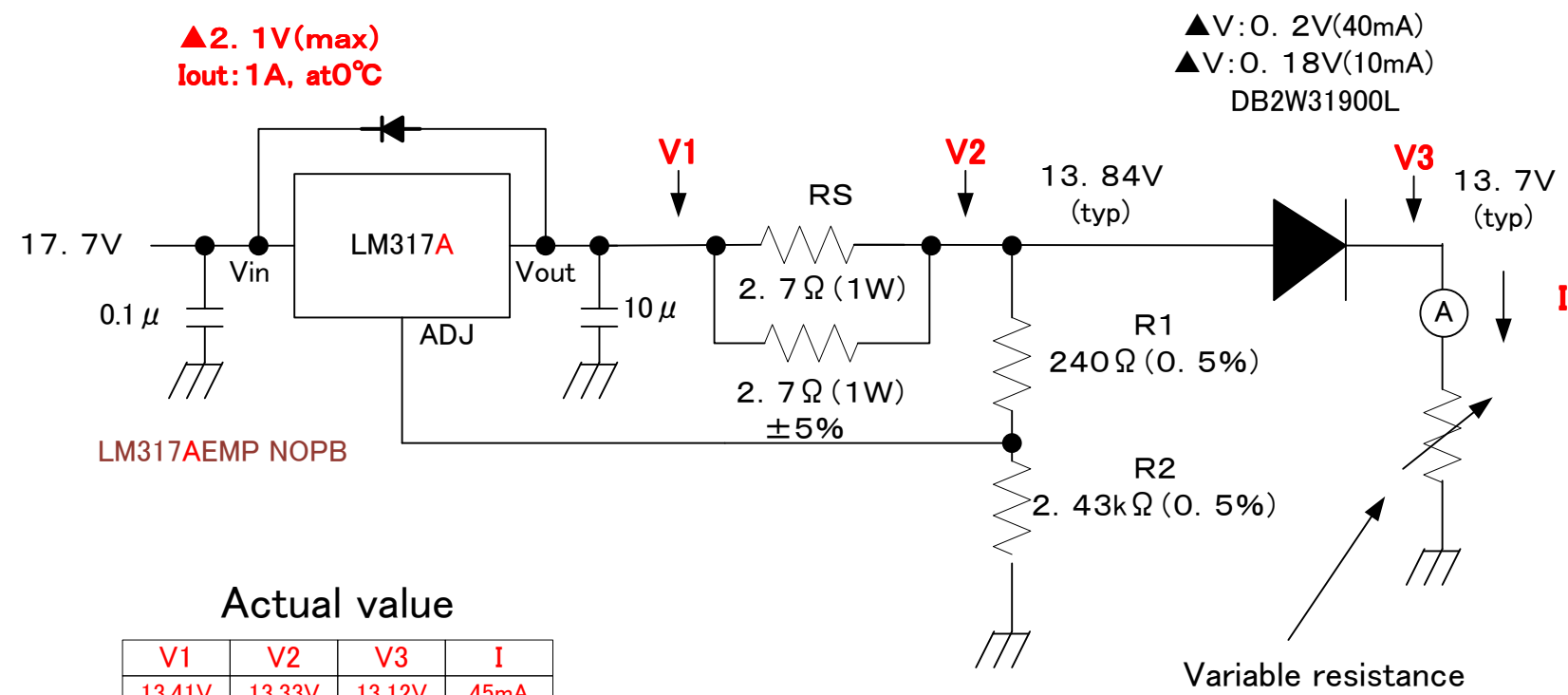

Actual value

V1	V2	V3	I
13.41V	13.33V	13.12V	45mA
13.00V	12.88V	12.65V	76mA
12.06V	11.85V	11.61V	144mA
10.86V	10.54V	10.28V	232mA
9.90V	9.48V	9.21V	300mA
7.81V	7.18V	6.88V	440mA
3.92V	3.47V	2.50V	330mA
3.72V	3.30V	2.36V	310mA
3.30V	2.88V	2.01V	300mA
3.24V	2.83V	1.61V	300mA

What value of the current limit of this circuit?